

Technical data sheet

1015 D fastening clip

Item number: 1009459



Fastening clip with a central fastening point for 2 cables or 2 pipes



- St Steel
- G Electrogalvanized

Master data		
Item number	1009459	
Type	1015 D 7 G	
Description 1	Fastening clip	
Description 2	for 2 cables	
Manufacturer	OBO	
Dimension	7mm	
Material	Steel	
Surface	Electrogalvanized	
Surface standard	EN ISO 19598 / EN ISO 4042	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	1.07 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,0099 kg COe / 1 Piece	


Technical data sheet

1015 D fastening clip

Item number: 1009459



Dimensions

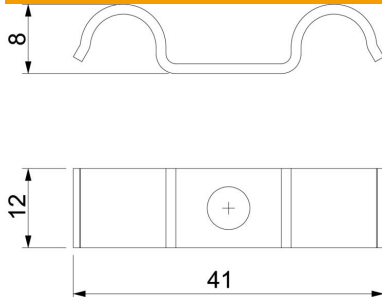

Length	41 mm
Width	12 mm
Height	8 mm
Dimension A	41 mm
Dimension b	12 mm
Dimension H	8 mm

Technical data

Distance to the wall	no
Number of cables/pipes	2
Version for	Single-lobe
Fastening type	Screw hole
For diameter	7
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 mm
Material thickness	1.5 mm
Nominal diameter	7 mm
Clamping range D, min.	7 mm
UV-resistant	yes