


# Technical data sheet

Roof cable holder for slated roofs, crimped, Rd 8–10, CU

Item number: 5215854



- Conductor holder of polyamide
- With  $\varnothing$  5.5 mm drill hole

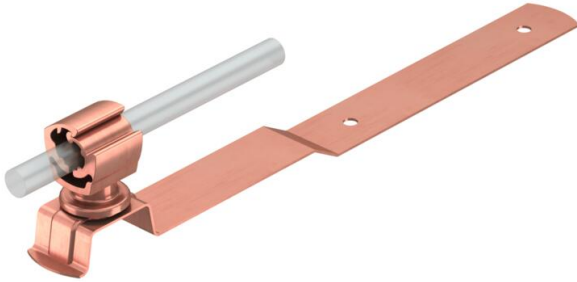


**Cu** Copper

## Master data

Item number	5215854
Type	157 EK-CU
Description 1	Roof conductor holder
Manufacturer	OBO
Dimension	8mm
Material	Copper
Smallest sales unit	10
Unit of quantity	Piece
Weight	8.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2493 kg CO2e / 1 Piece

## Dimensions

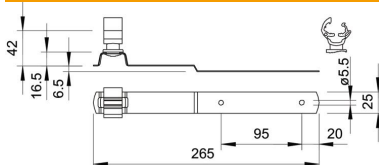

Length	265 mm
--------	--------

# Technical data sheet

Roof cable holder for slated roofs, crimped, Rd 8–10, CU

Item number: 5215854



## Technical data

Application	Roof surface
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Screw-on
Mounting height	42 mm
Fit	Rd 8-10 mm
Material of the holder	Plastic
Material of the support	Copper