


Technical data sheet

Roof conductor holder for tiled roofs, Rd 8–10

Item number: 5216214



- Conductor holder of polyamide
- Including drill hole in bottom section for quick installation

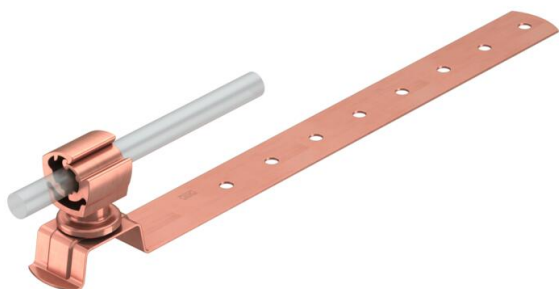


Cu Copper

Master data

Item number	5216214
Type	157 FK-CU 280
Description 1	Roof conductor holder
Manufacturer	OBO
Dimension	8mm
Material	Copper
Smallest sales unit	10
Unit of quantity	Piece
Weight	9.6 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2481 kg CO2e / 1 Piece

Dimensions

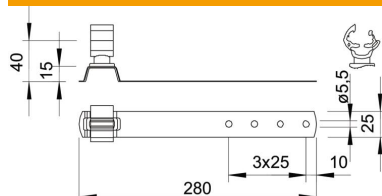

Length	280 mm
Dimension L	280 mm

Technical data sheet

Roof conductor holder for tiled roofs, Rd 8–10

Item number: 5216214



Technical data

Application	Roof surface
Conductor fastening type	With clamp clip
Conductor diameter, max.	10
Conductor diameter, min.	8
Mounting type	Screw-on
Mounting height	40 mm
Fit	Rd 8-10 mm
Material of the holder	Plastic
Material of the support	Copper