


# Technical data sheet

## Roof conductor holder for tiled roofs, angled, Rd 8, CU

Item number: 5215749



- Conductor holder copper plated high-grade stainless steel (V2A)
- Curved bottom strip for quick installation

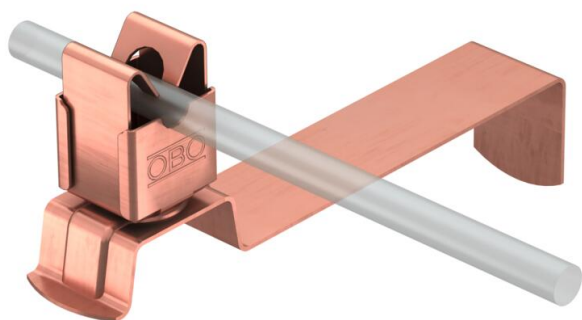

**Cu** Copper

### Master data

Item number	5215749
Type	157 I-CU
Description 1	Roof conductor holder
Manufacturer	OBO
Dimension	8mm
Material	Copper
Smallest sales unit	10
Unit of quantity	Piece
Weight	7.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1756 kg CO2e / 1 Piece


# Technical data sheet

## Roof conductor holder for tiled roofs, angled, Rd 8, CU



Item number: 5215749

### Dimensions

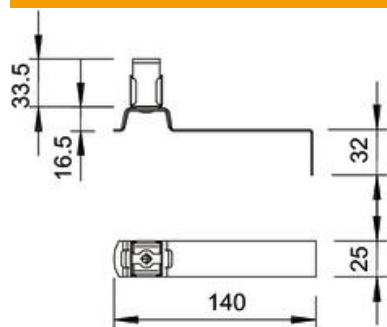

Length 140 mm

### Technical data

Application	Roof surface
Conductor fastening type	With clip
Conductor diameter, max.	8
Conductor diameter, min.	8
Mounting type	For suspension
Mounting height	26.5 mm
Fit	Rd 8 mm
Material of the holder	Copper
Material of the support	Copper