

Technical data sheet

Locknut, metric thread with cutting teeth

Item number: 2091717



Locknuts DIN 46319 with metric thread IEC 423.

* Prices according to DEL notation.



CuZn
37 Brass

N Nickel-plated

Master data

Item number	2091717
Type	169 MSS M25
Description 1	Locknut
Description 2	with cutting teeth
Manufacturer	OBO
Dimension	M25x1,5
Material	Brass
Surface	Nickel-plated
Surface standard	
Smallest sales unit	50
Unit of quantity	Piece
Weight	1.19 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0021 kg COe / 1 Piece


Technical data sheet

Locknut, metric thread with cutting teeth

Item number: 2091717



Dimensions

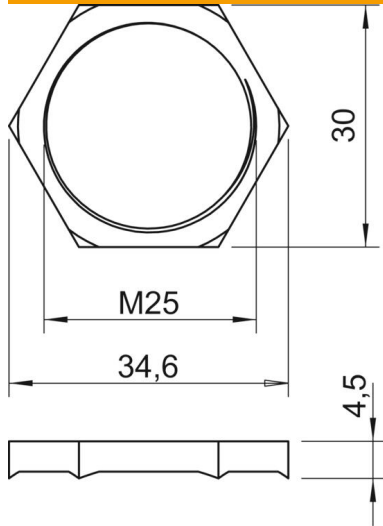

Dimension E	34.6 mm
Dimension L	4.5 mm

Technical data

Thread	M25_x_1,5
Thread type	Metric
Nominal thread size metric/PG	25
Fibre-glass reinforced	no
Halogen-free	no
Impact-resistant	no
WAF	30