

Technical data sheet

Cable bracket Rd 8–10 mm, with wood screw thread

Item number: 5227089



- Also for flat conductor to FL 30
- With wood screw thread
- Bottom section, hot-dip galvanised cast iron
- Over-piece and screws, hot dipped galvanised steel

TG Cast iron

F Hot galvanized

Master data

Item number	5227089
Type	176 A 80
Description 1	Cable fixing device
Manufacturer	OBO
Dimension	80mm
Material	Cast iron
Surface	Hot galvanized
Surface standard	DIN 267, Teil 10
Smallest sales unit	50
Unit of quantity	Piece
Weight	10.025 kg
Weight unit	kg/100 pc.


Technical data sheet

Cable bracket Rd 8–10 mm, with wood screw thread



Item number: 5227089

Dimensions

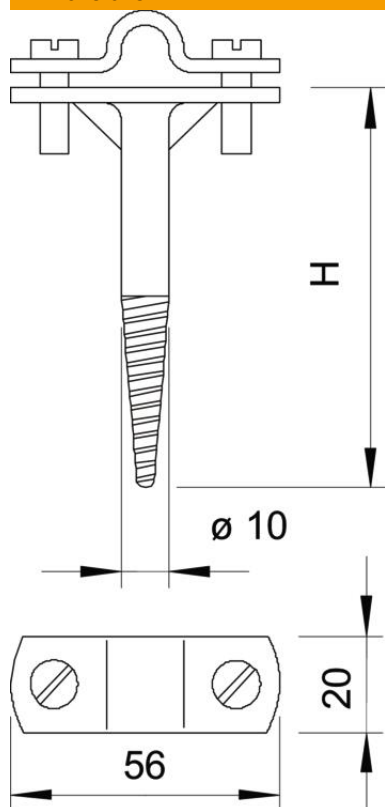

Length	80 mm
Dimension H	80 mm

Technical data

Holder fastening type	With wood screw thread tip
Conductor fastening type	With screw clip
Use in Ex area	yes
High voltage-resistant, insulated version	no
Cable dimensions	8–10 mm round
Fit	Rd 8-10 mm
Material of the holder	Malleable iron
Material of the base	Malleable iron
Material of the crossbar	Malleable iron