

# Technical data sheet

## Adhesive clip 2027, light grey

Item number: 2232940



Adhesive clip, for clamping to the cable.



PP

Polypropylene

### Master data

|                     |                      |
|---------------------|----------------------|
| Item number         | 2232940              |
| Type                | 2027 40 LGR SO       |
| Description 1       | Self-retaining clip  |
| Manufacturer        | OBO                  |
| Dimension           | 10-14mm, L40         |
| Colour              | Light grey; RAL 7035 |
| Material            | Polypropylene        |
| Smallest sales unit | 150                  |
| Unit of quantity    | Piece                |
| Weight              | 0.196 kg             |
| Weight unit         | kg/100 pc.           |


# Technical data sheet

Adhesive clip 2027, light grey

Item number: 2232940



## Dimensions

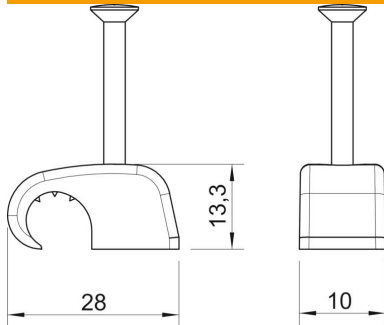

|             |         |
|-------------|---------|
| Dimension B | 10 mm   |
| Dimension H | 13.3 mm |
| Dimension L | 28 mm   |

## Technical data

|                          |                             |
|--------------------------|-----------------------------|
| Double clip              | no                          |
| Shape                    | Round (for round conductor) |
| for cable diameter, max. | 14 mm                       |
| for cable diameter, min. | 10 mm                       |
| For nail diameter        | 2,0 x 40                    |
| Hardened                 | yes                         |
| Halogen-free             | yes                         |
| With nail                | yes                         |
| Nail length              | 40 mm                       |
| Impact-resistant         | yes                         |
| Pipe locking             | no                          |