

Technical data sheet

Grip 10

Item number: 2205384



Collection clamp for general use with fastening holes of \varnothing 6 mm, suitable for wall and ceiling mounting. The moulded fastening element can be fastened using knock-in anchors or a gas pressure nail gun. The recommended fastening spacing when assigned fully is 50 to 60 cm.

Capacity:

2031/ 10 max. 10 cables NYM 3 x 1.5 mm²



PP Polypropylene

Master data

Item number	2205384
Type	2031 10 SP
Description 1	Grip collecting clamp
Description 2	with arrangement contour
Manufacturer	OBO
Dimension	10x NYM3x1,5
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.41 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0507 kg CO2e / 1 Piece


Technical data sheet

Grip 10

Item number: 2205384



Dimensions

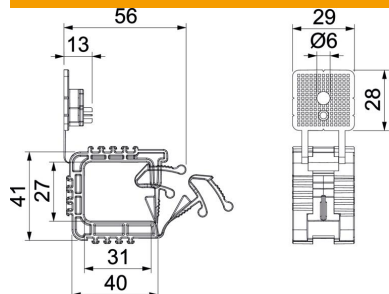

Technical data

No. of conductors NYM 3 x 1.5	10
Flame-resistant version	no
Breaking load	0.32 kN
Maintain electrical functions	no
Halogen-free	yes
With anchor	no