


Technical data sheet

Cover for WDK trunking, trunking width 230 mm

Item number: 6027504

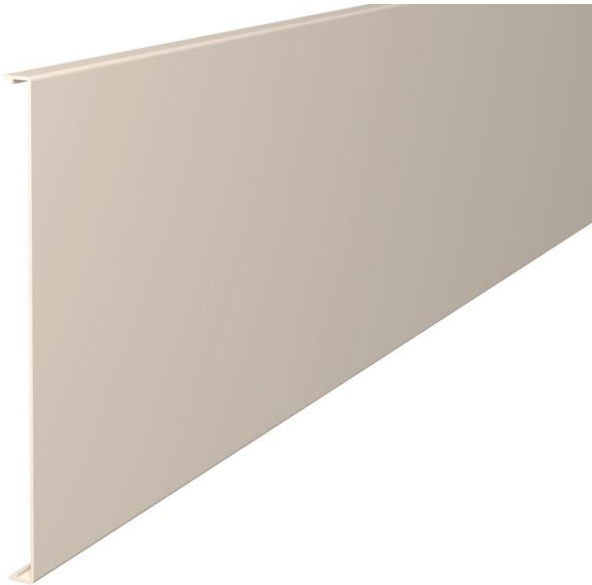

Cover for closing the trunking.



PVC Polyvinylchloride

Master data

Item number	6027504
Type	2410 230CW
Description 1	Cover
Description 2	for WDK
Manufacturer	OBO
Dimension	230x2000mm
Colour	Cream; RAL 9001
Material	Polyvinylchloride
Smallest sales unit	2
Unit of quantity	Metre
Weight	78.5 kg
Weight unit	kg/100 m
CO2 Footprint (GWP) Cradle-to-Gate	1,5986 kg CO2e / 1 Meter


Technical data sheet

Cover for WDK trunking, trunking width 230 mm

Item number: 6027504



Dimensions

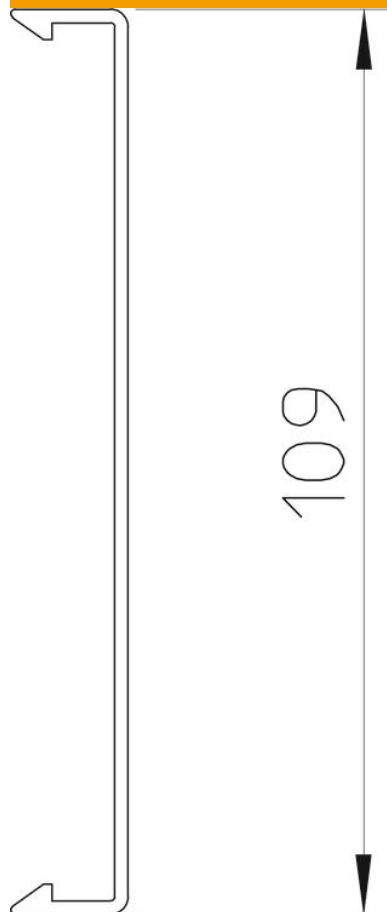

Length	2,000 mm
Width	230 mm

Technical data

Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C