


Technical data sheet

Cross-connector with intermediate plate for Rd 8–10 mm,
wide version A4

Item number: 5312294

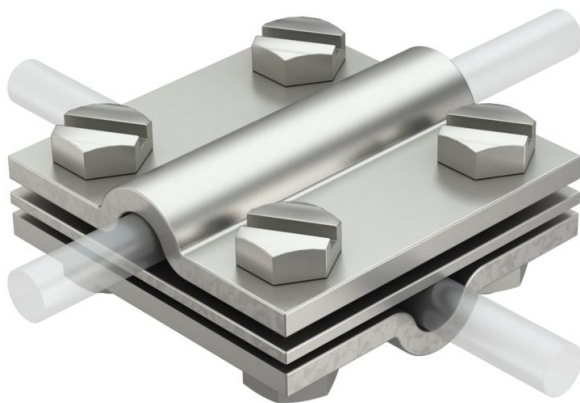

- Meets the requirements of VDE 0185-305-3 (IEC/ EN 62305-3)
- Fit: Rd 8-10 x Rd 8-10 / FL 30
- With adapter plate
- Mounted with 4 hexagonal bolts M8 x 25 and 4 hexagonal nuts M8



A4 Stainless steel

Master data

Item number	5312294
Description 1	Cross-connectors round/round
Description 2	with intermediate plate
Manufacturer	OBO
Dimension	8-10mm
Material	Stainless steel
Smallest sales unit	2800
Unit of quantity	Piece
Weight	28.8 kg
Weight unit	kg/100 pc.


 
Technical data sheet

Cross-connector with intermediate plate for Rd 8–10 mm,
wide version A4

Item number: 5312294



Dimensions

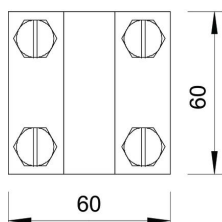

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Cross-connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Round conductor Rd 8–10 / Rd 8–10
Fit	Rd 8-10 mm
Intermediate plate	yes