


Technical data sheet

Cross-connector for round cables and flat conductors DIN FT

Item number: 5312302

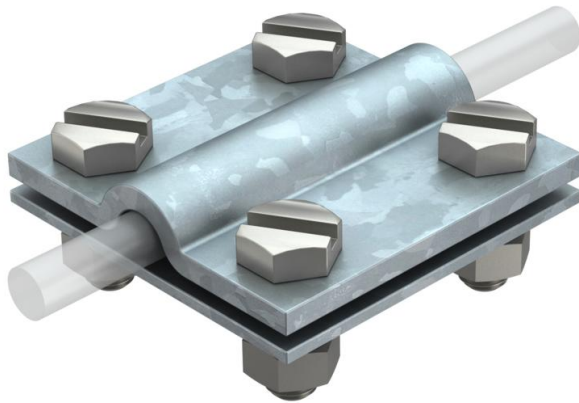

- Meets the requirements of VDE 0185-305-3 (IEC/ EN 62305-3)
- Fit: Rd 8-10 x FL 30
- Mounted with 4 hexagonal bolts M8 x 25 and 4 hexagonal nuts M8



St

Steel

FT

Hot-dip galvanised

Master data

Item number	5312302
Description 1	Cross-connectors round/flat
Description 2	no intermediate plate
Manufacturer	OBO
Dimension	8-10xFL30
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	3600
Unit of quantity	Piece
Weight	25 kg
Weight unit	kg/100 pc.


Technical data sheet

Cross-connector for round cables and flat conductors DIN FT


Item number: 5312302



Dimensions

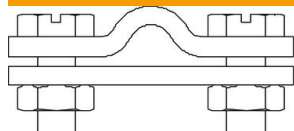

Dimension A	60 mm
Dimension B	60 mm

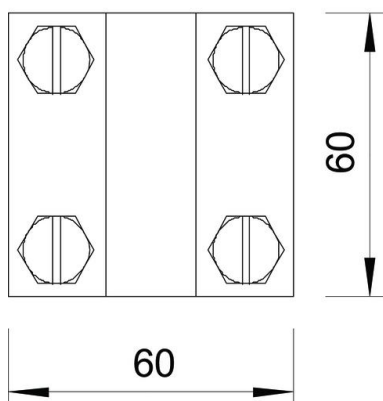

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Cross-connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Round conductor Rd 8-10 / flat conductor FI 30
Fit	Rd 8-10/FL30 mm
Intermediate plate	no