

Technical data sheet


DIN cross-connector for flat conductor A2

Item number: 5314720



256/A-DIN ...: Cross-connector for flat conductors

- Material: Stainless steel, material no. 1.4301
- Seat: Max. FL30 mm
- Without intermediate plate
- Mounted with 4 hexagonal bolts M8 x 25 and 4 hexagonal nuts M8
- DIN 48845, shape H

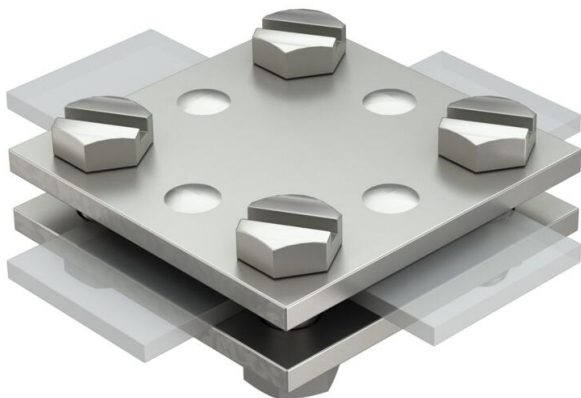

A2 Stainless steel

Master data

Item number	5314720
Type	256 A-DIN 30 VA
Description 1	Cross-connectors
Description 2	no separator plate
Manufacturer	OBO
Dimension	30mm
Material	Stainless steel 1.4301
Smallest sales unit	10
Unit of quantity	Piece
Weight	27.8 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	1,1874 kg CO2e / 1 Piece

Technical data sheet

DIN cross-connector for flat conductor A2


Item number: 5314720



Dimensions



Dimension A	60 mm
Dimension B	60 mm

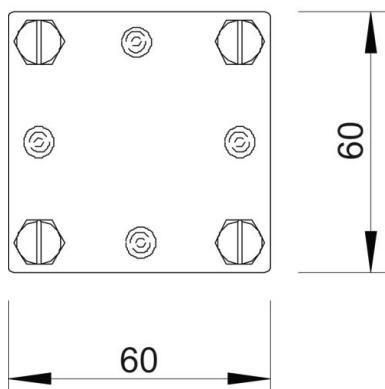

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Cross-connectors
Lightning current carrying capacity	H/100 kA
Suitable for connection	Flat conductor FI 30 / FI 30
Fit	max. FL30 mm
Intermediate plate	no