


Technical data sheet

Folding clamp up to 5 mm plate thickness Cu

Item number: 5317452



- Plate thickness to 5 mm
- For conductor routing transverse and longitudinal to plate
- With 4 hexagonal bolts M6 x 12
- Conforms to the requirements according to DIN VDE 0185-305 (IEC 62305)
- 271 Cu: with hexagonal bolts stainless steel (VA)

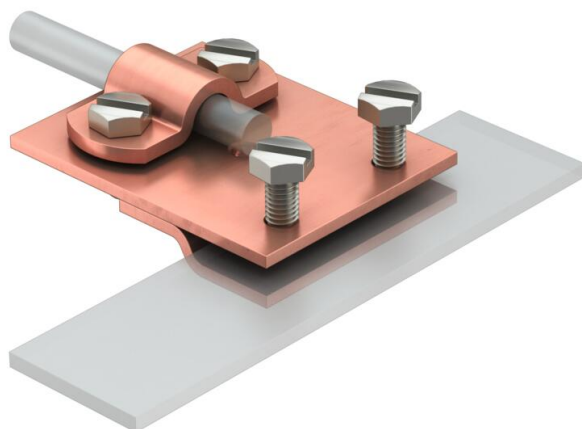

Cu Copper

Master data

Item number	5317452
Type	271 CU
Description 1	Folding clamp
Manufacturer	OBO
Dimension	8/10mm
Material	Copper
Smallest sales unit	10
Unit of quantity	Piece
Weight	15.23 kg
Weight unit	kg/100 pc.


Technical data sheet

Folding clamp up to 5 mm plate thickness Cu

Item number: 5317452



Dimensions

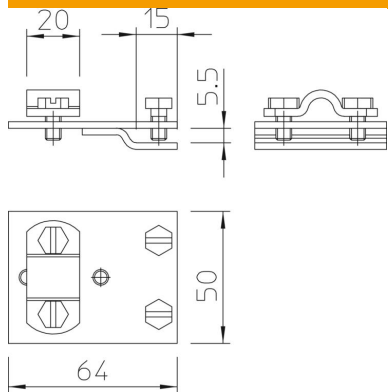

Technical data

Type of fastening screw	Hexagonal bolt
Type of connector	Folding clamp
Lightning current carrying capacity	N/50 kA
Fit	Rd 8-10 mm
Clamping range, max.	5 mm