

Technical data sheet

Quick clip, black

Item number: 2149563



Flush-mounted clip to accept metric steel armoured pipes and heavy-duty insulating pipes, as well as Quick-Pipe® electrical installation pipes. Universal fastening options on walls and ceilings, both in indoor and protected outdoor areas. With slot for side alignment during mounting with wood screw or knock-in anchor. Toolless pipe mounting. Can also be arranged with OBO Multi-Quick or proQuick clip. M16 - M32 size can be screwed onto M6 thread. Recommended fastening spacing 50–60 cm, for max. extraction values F at a room temperature of 20 °C, see the table.



PP Polypropylene

Master data

Item number	2149563
Type	2955 M20 SW
Description 1	Quick clip
Manufacturer	OBO
Dimension	M20
Colour	Jet black; RAL 9005
Material	Polypropylene
Smallest sales unit	100
Unit of quantity	Piece
Weight	0.325 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0151 kg CO2e / 1 Piece


Technical data sheet

Quick clip, black

Item number: 2149563



Dimensions

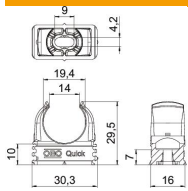

Dimension A	30.3 mm
Dimension B	16 mm
Dimension C	14 mm
Dimension D	19.4 mm
Dimension E	9 mm
Dimension F	4.2 mm
Dimension h	10 mm
Dimension H	29.5 mm

Technical data

Expandable	yes
Number of cables/pipes	1
Pull-out value	75 N
Fastening type	Screw hole
Closed	no
Halogen-free	yes
With inlay	no
Nominal size	M20
Quick clip installation	Durchgangsloch, auf M6 Gewinde aufschraubbar
UV-resistant	no