

Technical data sheet

Quick clip, black

Item number: 2149583



Flush-mounted clip to accept metric steel armoured pipes and heavy-duty insulating pipes, as well as Quick-Pipe® electrical installation pipes. Universal fastening options on walls and ceilings, both in indoor and protected outdoor areas. With slot for side alignment during mounting with wood screw or knock-in anchor. Toolless pipe mounting. Can also be arranged with OBO Multi-Quick or proQuick clip. M16 - M32 size can be screwed onto M6 thread. Recommended fastening spacing 50–60 cm, for max. extraction values F at a room temperature of 20 °C, see the table.



PP Polypropylene

Master data

| | |
|------------------------------------|--------------------------|
| Item number | 2149583 |
| Type | 2955 M63 SW |
| Description 1 | Quick clip |
| Manufacturer | OBO |
| Dimension | M63 |
| Colour | Jet black; RAL 9005 |
| Material | Polypropylene |
| Smallest sales unit | 20 |
| Unit of quantity | Piece |
| Weight | 2.203 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0894 kg CO2e / 1 Piece |


Technical data sheet

Quick clip, black

Item number: 2149583



Dimensions

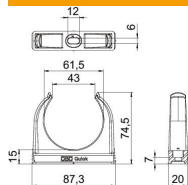

| | |
|-------------|---------|
| Dimension A | 87.3 mm |
| Dimension B | 20 mm |
| Dimension C | 43 mm |
| Dimension D | 61.5 mm |
| Dimension E | 12 mm |
| Dimension F | 6 mm |
| Dimension h | 15 mm |
| Dimension H | 74.5 mm |

Technical data

| | |
|-------------------------|--|
| Expandable | yes |
| Number of cables/pipes | 1 |
| Pull-out value | 175 N |
| Fastening type | Screw hole |
| Closed | no |
| Halogen-free | yes |
| With inlay | no |
| Nominal size | M63 |
| Quick clip installation | Durchgangsloch, auf M6 Gewinde aufschraubbar |
| UV-resistant | no |