


# Technical data sheet

## Base clamp clip, double

Item number: 2140683

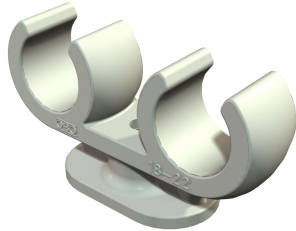

Base clamp clip, two cables 15–16 mm



**PP** Polypropylene

### Master data

Item number	2140683
Type	2962 2x16
Description 1	Base clamp
Description 2	for 2 cables
Manufacturer	OBO
Dimension	15-16mm
Colour	Light grey; RAL 7035
Material	Polypropylene
Smallest sales unit	50
Unit of quantity	Piece
Weight	0.809 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,0313 kg COe / 1 Piece


# Technical data sheet

## Base clamp clip, double

Item number: 2140683



### Dimensions

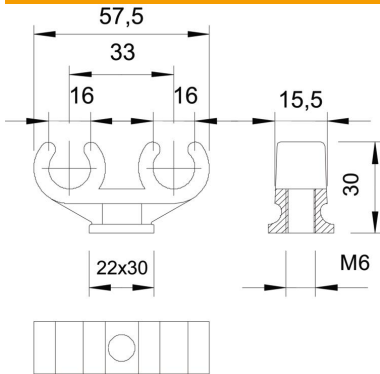

Dimension A	57.5 mm
Dimension B	15.5 mm
Dimension C	20 x 33 mm
Dimension H	30 mm
Dimension L	33 mm

### Technical data

Number of cables/pipes	2
Version for	Two-lobe
Fastening type	Threaded connection
Suitable in fire protection area	no
Size	15/16 + 15/16
Halogen-free	yes
Plastic-covered	no
Nominal diameter	14.7 mm
Clamping range D, max.	16 mm
Clamping range D, min.	15 mm
UV-resistant	no