


# Technical data sheet

## Lightning ISO clip

Item number: 2157349

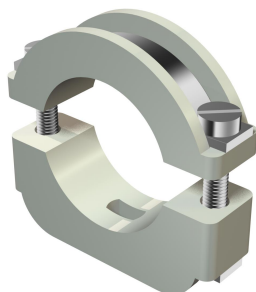

Lightning ISO clips: plastic clip with metal insert, therefore also suitable for heavy-duty applications; metal parts made of electrogalvanised steel.  
3015 with 4.5 mm slot.

\*Sizes 6–12 and 10–17 not suitable for bolt-firing device.



PS Polystyrene

### Master data

Item number	2157349
Type	3015 34 LGR
Description 1	Lightning ISO clip
Description 2	with slot
Manufacturer	OBO
Dimension	24-34mm
Colour	Light grey; RAL 7035
Material	Polystyrene
Smallest sales unit	25
Unit of quantity	Piece
Weight	3.62 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1298 kg CO2e / 1 Piece


# Technical data sheet

## Lightning ISO clip

Item number: 2157349



### Dimensions

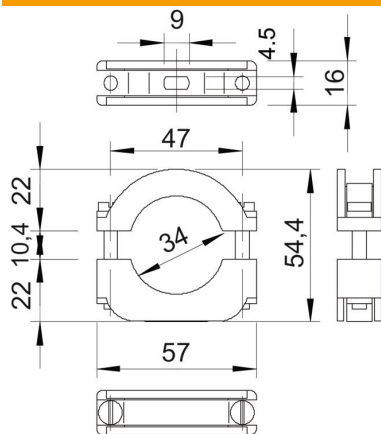

Dimension A	57 mm
Dimension B	47 mm
Dimension b	16 mm
Dimension D	34 mm
Dimension H	54.4 mm
Dimension Ho (mm)	22
Dimension Hu (mm)	22
Dimension L	9 mm

### Technical data

Number of cables/pipes	1
Version for	Closed
Fastening type	Screw hole
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Bolt	M5 x 35
Clamping range D, max.	34 mm
Clamping range D, min.	24 mm
UV-resistant	no