

Technical data sheet

Sprint screw, with Torx

Item number: 3198062



Steel, hardened, electro-galvanised and yellow-passivated and with Hostafion coating, panhead with T bit (hexalobular) of sizes Ø 3 mm T10, Ø 3.5 mm T15, Ø 4 and 4.5 mm T20, Ø 5 mm T25.

The use of SPRINT screws leads to considerably reduced screwing times compared with standard screws. This clear advantage is created by the biting tip with the first thread, which leads to the double thread.

Areas of use: wood, chipboard, plasterboard, plastic anchors.



St Steel

G Electrogalvanized

Master data

Item number	3198062
Description 1	Sprint screw
Description 2	panhead, T-drive
Manufacturer	OBO
Dimension	4,5x50mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	200
Unit of quantity	Piece
Weight	0.393 kg
Weight unit	kg/100 pc.


Technical data sheet

Sprint screw, with Torx

Item number: 3198062



Dimensions

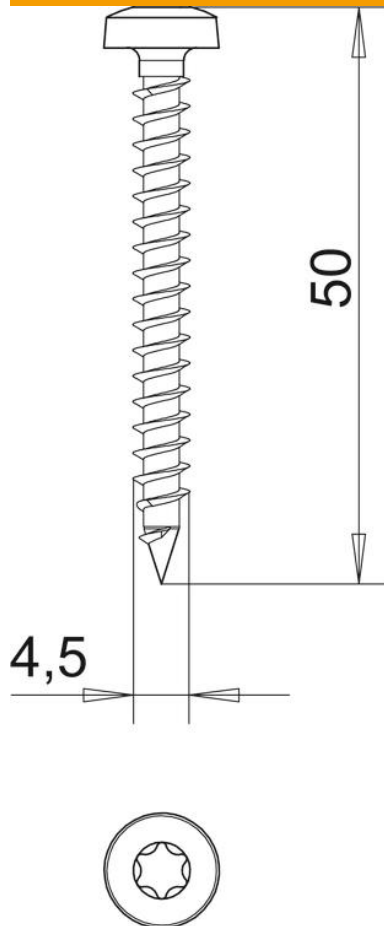

Length	50 mm
Dimension D	4.5 mm
Dimension L	50 mm

Technical data

Hardened	yes
Head diameter	8.2 mm
Head shape	Panhead
Screw system	Torx
Two-compartment	yes