

Technical data sheet

Sprint screw, with Philips screw


Item number: 3195015



Hardened steel, electrogalvanised and Hostaflon-coated. Pan head with combined Phillips and slotted head (Pozidriv size 2 except Ø 6 mm Pozidriv size 3).

The use of Sprint screws leads to considerably reduced screw-in times compared with standard screws. This noticeable advantage comes from the point with the first thread, which leads on to the double thread beyond.

Areas of use: wood, chipboard, Rigips panels, plastic anchors.

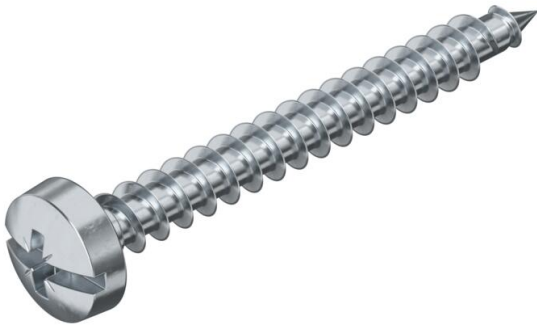

St

Steel

G

Electrogalvanized

Master data

Item number	3195015
Type	4758 3.5x20
Description 1	Sprint screw
Description 2	panhead, +/- slot drive
Manufacturer	OBO
Dimension	3,5x20mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	200
Unit of quantity	Piece
Weight	0.09 kg
Weight unit	kg/100 pc.


Technical data sheet

Sprint screw, with Philips screw

Item number: 3195015



Dimensions

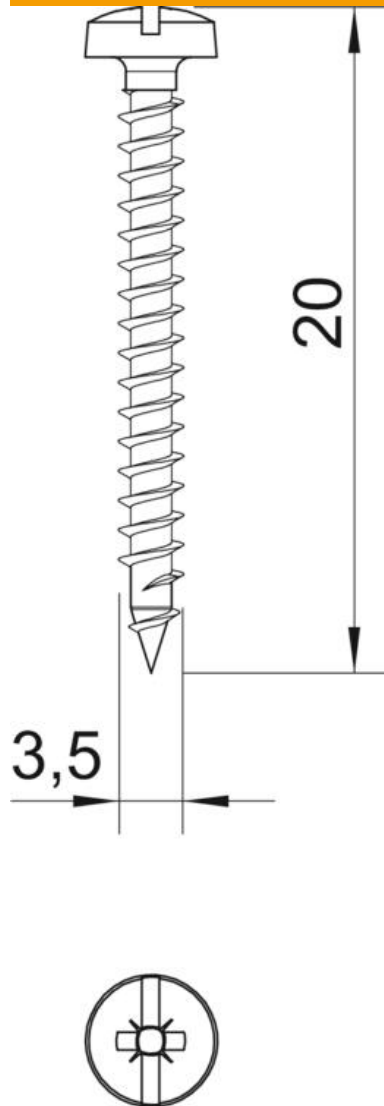

Length	20 mm
Dimension D	3.5 mm
Dimension L	20 mm

Technical data

Hardened	yes
Head diameter	6.5 mm
Head shape	Panhead
Screw system	Combination slot
Two-compartment	yes