

Technical data sheet

Connection and end piece A4



Item number: 5334942




- For attaching to steel structures or bolting to fixed earthing terminals
- For attachments: Round conductor Rd 8-10 and flat conductor FL 30 x 3.5
- 2 attaching holes \varnothing 11 mm
- 1 attaching hole \varnothing D mm

A4 Stainless steel

Master data

Item number	5334942
Type	5011 VA M12
Description 1	End piece
Manufacturer	OBO
Dimension	M12
Material	Stainless steel
Smallest sales unit	10
Unit of quantity	Piece
Weight	7.048 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,4046 kg CO2e / 1 Piece

Dimensions

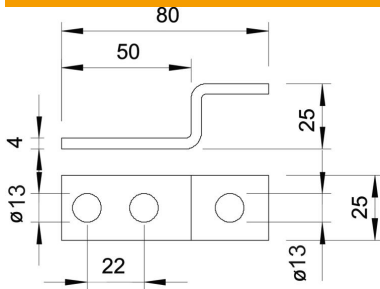

Dimension d min. | 13 mm

Technical data

Type of fastening screw	Miscellaneous
Type of connector	End piece
Suitable for connection	Round conductor Rd 8-10 / flat conductor FI 30
Intermediate plate	no