

Technical data sheet

Fastening clip 605, medium duty, V4A

Item number: 1018729



Two lobe fastening clips for cables and pipes.



A4 Stainless steel

2B Bright, treated

Master data

Item number	1018729
Description 1	Fastening clip
Description 2	two lobe
Manufacturer	OBO
Dimension	63mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	25
Unit of quantity	Piece
Weight	3.67 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1988 kg COe / 1 Piece


Technical data sheet

Fastening clip 605, medium duty, V4A

Item number: 1018729



Dimensions

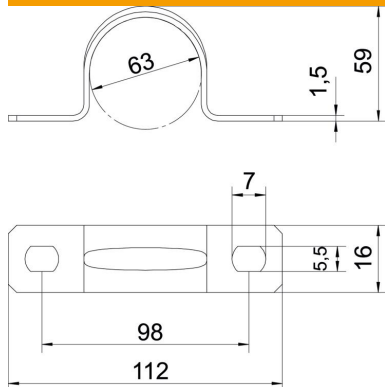

Length	112 mm
Width	16 mm
Height	59 mm
Dimension A	112 mm
Dimension B	98 mm
Dimension b	16 mm
Dimension D	63 mm
Dimension d	5.5 mm
Dimension e	7 mm
Dimension H	59 mm
Dimension t	1.5 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Two-lobe
Fastening type	Screw hole
For diameter	63
Suitable in fire protection area	no
Halogen-free	yes
Plastic-covered	no
Hole size	5,5 x 7 mm
Material thickness	1.5 mm
Nominal diameter	63 mm
UV-resistant	yes