

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014021



Fastening clip, single-lobe, 12 mm



- St

Steel
- FT

Hot-dip galvanised

Master data		
Item number	1014021	
Type	822 12 FT	
Description 1	Fastening clip	
Description 2	single lobe	
Manufacturer	OBO	
Dimension	12mm	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	1.45 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,0329 kg COe / 1 Piece	


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014021



Dimensions

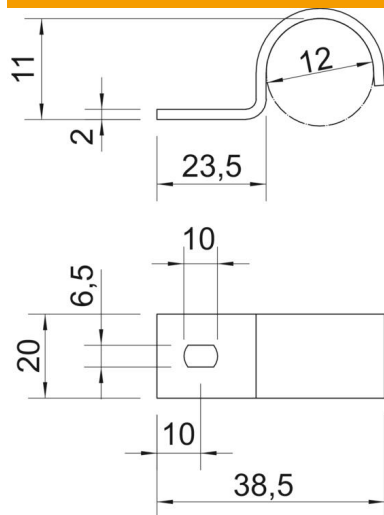

Length	38.5 mm
Width	20 mm
Height	11 mm
Dimension A	10 mm
Dimension b	20 mm
Dimension D	12 mm
Dimension H	11 mm
Dimension L	23.5 mm
Dimension L1	38.5 mm
Dimension t	2 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	12
Suitable in fire protection area	no
Size	M12
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10 mm
Material thickness	2 mm
Nominal diameter	12 mm
UV-resistant	yes