

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014099



Fastening clip, single-lobe, 16 mm



- St

Steel
- FT

Hot-dip galvanised

Master data		
Item number	1014099	
Description 1	Fastening clip	
Description 2	single lobe	
Manufacturer	OBO	
Dimension	16mm	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	1.733 kg	
Weight unit	kg/100 pc.	
CO Footprint (GWP) Cradle-to-Gate	0,0374 kg COe / 1 Piece	


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014099



Dimensions

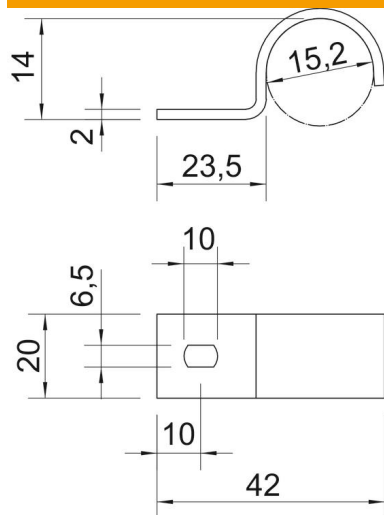

Length	42 mm
Width	20 mm
Height	14 mm
Dimension A	10 mm
Dimension b	20 mm
Dimension D	15.2 mm
Dimension H	14 mm
Dimension L	23.5 mm
Dimension L1	42 mm
Dimension t	2 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	15,2
Suitable in fire protection area	no
Size	M16
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10 mm
Material thickness	2 mm
Nominal diameter	15.2 mm
UV-resistant	yes