

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014110



Fastening clip, single-lobe, 19 mm



- St

Steel
- FT

Hot-dip galvanised

Master data	
Item number	1014110
Type	822 18 FT
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	19mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	100
Unit of quantity	Piece
Weight	1.946 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,0415 kg COe / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014110



Dimensions

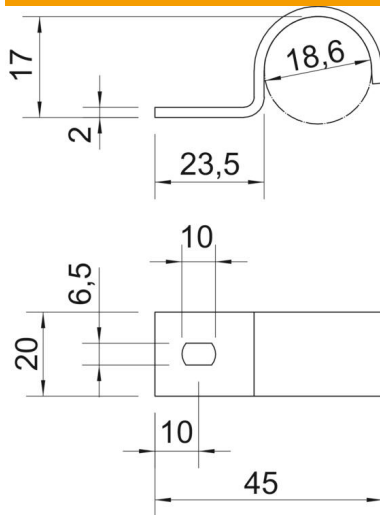

Length	45 mm
Width	20 mm
Height	17 mm
Dimension A	10 mm
Dimension b	20 mm
Dimension D	18.6 mm
Dimension H	17 mm
Dimension L	23.5 mm
Dimension L1	45 mm
Dimension t	2 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	18,6
Suitable in fire protection area	no
Size	PG11
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10 mm
Material thickness	2 mm
Nominal diameter	18.6 mm
UV-resistant	yes