

# Technical data sheet

## Fastening clip 822, heavy duty, FT

Item number: 1014218



Fastening clip, single-lobe, 28 mm



|    |                    |
|----|--------------------|
| St | Steel              |
| FT | Hot-dip galvanised |

### Master data

|                                    |                         |
|------------------------------------|-------------------------|
| Item number                        | 1014218                 |
| Type                               | 822 28.3 FT             |
| Description 1                      | Fastening clip          |
| Description 2                      | single lobe             |
| Manufacturer                       | OBO                     |
| Dimension                          | 28mm                    |
| Material                           | Steel                   |
| Surface                            | Hot-dip galvanised      |
| Surface standard                   | DIN EN ISO 1461         |
| Smallest sales unit                | 50                      |
| Unit of quantity                   | Piece                   |
| Weight                             | 4.42 kg                 |
| Weight unit                        | kg/100 pc.              |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,0889 kg COe / 1 Piece |


# Technical data sheet

## Fastening clip 822, heavy duty, FT

Item number: 1014218



### Dimensions

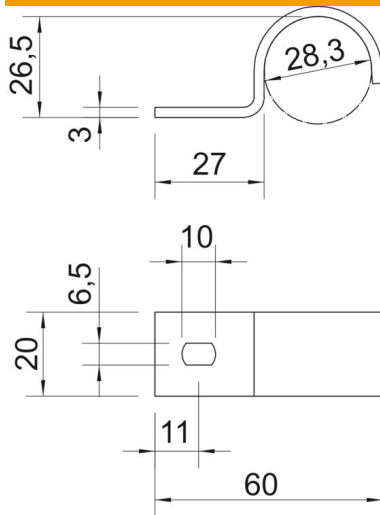

|              |         |
|--------------|---------|
| Length       | 60 mm   |
| Width        | 20 mm   |
| Height       | 26.5 mm |
| Dimension A  | 11 mm   |
| Dimension b  | 20 mm   |
| Dimension D  | 28.3 mm |
| Dimension H  | 26.5 mm |
| Dimension L  | 27 mm   |
| Dimension L1 | 60 mm   |
| Dimension t  | 3 mm    |

### Technical data

|                                  |             |
|----------------------------------|-------------|
| Distance to the wall             | no          |
| Number of cables/pipes           | 1           |
| Version for                      | Single-lobe |
| Fastening type                   | Screw hole  |
| For diameter                     | 28,3        |
| Suitable in fire protection area | no          |
| Size                             | PG21        |
| Halogen-free                     | yes         |
| Plastic-covered                  | no          |
| Hole size                        | 6,5 x 10 mm |
| Material thickness               | 2 mm        |
| Nominal diameter                 | 28.3 mm     |
| UV-resistant                     | yes         |