

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014528



Fastening clip, single-lobe, 32 mm



- St

Steel
- FT

Hot-dip galvanised

Master data	
Item number	1014528
Type	822 32 FT
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	32mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	100
Unit of quantity	Piece
Weight	5.49 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,1561 kg COe / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014528



Dimensions

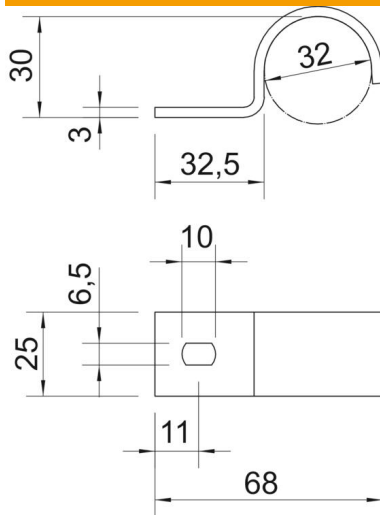

Length	68 mm
Width	25 mm
Height	30 mm
Dimension A	13 mm
Dimension b	25 mm
Dimension D	32 mm
Dimension H	30 mm
Dimension L	32.5 mm
Dimension L1	68 mm
Dimension t	3 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	32
Suitable in fire protection area	no
Size	M32
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10 mm
Material thickness	2 mm
Nominal diameter	32 mm
UV-resistant	yes