

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014536



Fastening clip, single-lobe, 40 mm



St	Steel
FT	Hot-dip galvanised

Master data

Item number	1014536
Type	822 40 FT
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	40mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	100
Unit of quantity	Piece
Weight	6.59 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,1853 kg COe / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014536



Dimensions

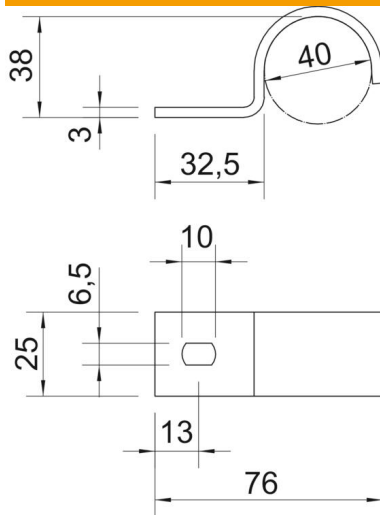

Length	76 mm
Width	25 mm
Height	38 mm
Dimension A	13 mm
Dimension b	25 mm
Dimension D	40 mm
Dimension H	38 mm
Dimension L	32.5 mm
Dimension L1	76 mm
Dimension t	3 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	40
Suitable in fire protection area	no
Size	M40
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10 mm
Material thickness	2 mm
Nominal diameter	40 mm
UV-resistant	yes