

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014366



Fastening clip, single-lobe, 47 mm



- St

Steel
- FT

Hot-dip galvanised

Master data		
Item number	1014366	
Type	822 47 FT	
Description 1	Fastening clip	
Description 2	single lobe	
Manufacturer	OBO	
Dimension	47mm	
Material	Steel	
Surface	Hot-dip galvanised	
Surface standard	DIN EN ISO 1461	
Smallest sales unit	100	
Unit of quantity	Piece	
Weight	8.5 kg	
Weight unit	kg/100 pc.	
CO2 Footprint (GWP) Cradle-to-Gate	0,1614 kg COe / 1 Piece	


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014366



Dimensions

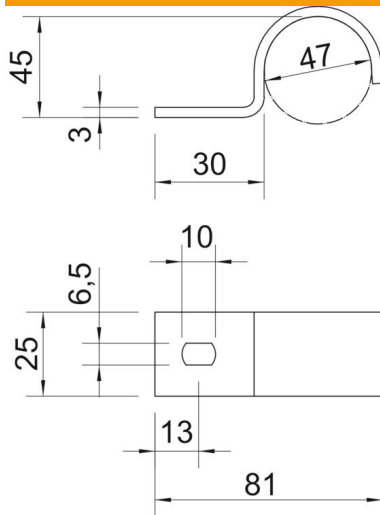

Length	81 mm
Width	25 mm
Height	45 mm
Dimension A	13 mm
Dimension b	25 mm
Dimension D	47 mm
Dimension H	45 mm
Dimension L	30 mm
Dimension L1	81 mm
Dimension t	3 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	47
Suitable in fire protection area	no
Size	PG36
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10 mm
Material thickness	3 mm
Nominal diameter	47 mm
UV-resistant	yes