

Technical data sheet

Fastening clip 822, heavy duty, A4

Item number: 1013921



Fastening clip, single-lobe, 50 mm



CE

A4 Stainless steel

2B Bright, treated

Master data

| | |
|------------------------------------|-------------------------|
| Item number | 1013921 |
| Type | 822 50 A4 |
| Description 1 | Fastening clip |
| Description 2 | single lobe |
| Manufacturer | OBO |
| Dimension | 50mm |
| Material | Stainless steel |
| Surface | Bright, treated |
| Surface standard | |
| Smallest sales unit | 100 |
| Unit of quantity | Piece |
| Weight | 7.69 kg |
| Weight unit | kg/100 pc. |
| CO2 Footprint (GWP) Cradle-to-Gate | 0,4313 kg COe / 1 Piece |


Technical data sheet

Fastening clip 822, heavy duty, A4

Item number: 1013921



Dimensions

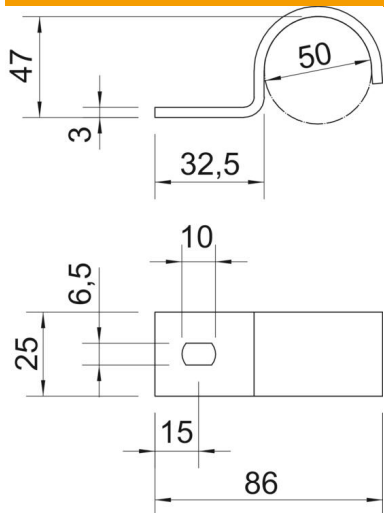

| | |
|--------------|---------|
| Length | 86 mm |
| Width | 25 mm |
| Height | 47 mm |
| Dimension A | 15 mm |
| Dimension b | 25 mm |
| Dimension D | 50 mm |
| Dimension H | 47 mm |
| Dimension L | 32.5 mm |
| Dimension L1 | 86 mm |
| Dimension t | 3 mm |

Technical data

| | |
|----------------------------------|-------------|
| Distance to the wall | no |
| Number of cables/pipes | 1 |
| Version for | Single-lobe |
| Fastening type | Screw hole |
| For diameter | 50 |
| Suitable in fire protection area | no |
| Size | M50 |
| Halogen-free | yes |
| Plastic-covered | no |
| Hole size | 6,5 x 10 mm |
| Material thickness | 3 mm |
| Nominal diameter | 50 mm |
| UV-resistant | yes |