

Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014552



Fastening clip, single-lobe, 63 mm



St

Steel

FT

Hot-dip galvanised

Master data

Item number	1014552
Type	822 63 FT
Description 1	Fastening clip
Description 2	single lobe
Manufacturer	OBO
Dimension	63mm
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	100
Unit of quantity	Piece
Weight	9.26 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2101 kg CO2e / 1 Piece


Technical data sheet

Fastening clip 822, heavy duty, FT

Item number: 1014552



Dimensions

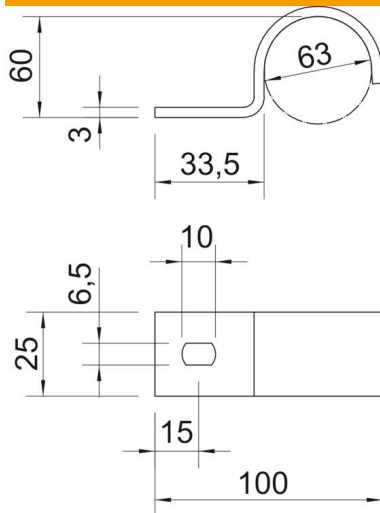

Length	100 mm
Width	25 mm
Height	60 mm
Dimension A	15 mm
Dimension b	25 mm
Dimension D	63 mm
Dimension H	60 mm
Dimension L	33.5 mm
Dimension L1	100 mm
Dimension t	3 mm

Technical data

Distance to the wall	no
Number of cables/pipes	1
Version for	Single-lobe
Fastening type	Screw hole
For diameter	63
Suitable in fire protection area	no
Size	M63
Halogen-free	yes
Plastic-covered	no
Hole size	6,5 x 10 mm
Material thickness	3 mm
Nominal diameter	63 mm
UV-resistant	yes