

Technical data sheet

Earthing pipe clamp VA

Item number: 5057523




- For pipes of Ø 3/8 - 6"
- Connection options: Max. 2 cables 2.5-25 mm²
- Round conductor Rd 8
- Clamp element, bolts and tightening strap made of rustproof stainless steel (VA)



A2 Stainless steel

Master data	
Item number	5057523
Description 1	Strip earthing clip
Manufacturer	OBO
Dimension	3/8-4"
Material	Stainless steel
Smallest sales unit	10
Unit of quantity	Piece
Weight	8.55 kg
Weight unit	kg/100 pc.
CO Footprint (GWP) Cradle-to-Gate	0,5452 kg COe / 1 Piece

Dimensions	
Dimension L	395 mm

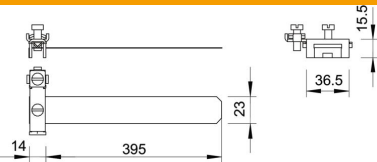

Technical data sheet

Earthing pipe clamp VA

Item number: 5057523



Technical data

Number of conductors	2
Lightning current carrying capacity	N/50 kA
For pipe diameter, max.	114 mm
For pipe diameter, min.	17.2 mm
Cross-section of cable to be connected, max.	25 mm ²
Cross-section of cable to be connected, min.	2.5 mm ²
Clamping range D	3/8 - 4
Clamping range D, max.	114 mm
Clamping range D, min.	17.2 mm