

Technical data sheet

Steel wire tensioning rope G

Item number: 5303206



Steel wire tensioning rope, galvanised with fibre inlay (hemp core).
Cable Ø 2–6 mm: round-stranded cable 6 x 7 according to DIN 3055.
Cable Ø 8–10 mm: round-stranded cable 6 x 19 according to DIN 3060.
Minimum break force 1770 N/mm².



St	Steel
G	Electrogalvanized

Master data

Item number	5303206
Description 1	Steel wire tensioning cable
Description 2	with hemp core
Manufacturer	OBO
Dimension	3mm
Material	Steel
Surface	Electrogalvanized
Surface standard	EN ISO 19598 / EN ISO 4042
Smallest sales unit	50
Unit of quantity	Metre
Weight	3.22 kg
Weight unit	kg/100 m


Technical data sheet

Steel wire tensioning rope G


Item number: 5303206



Dimensions

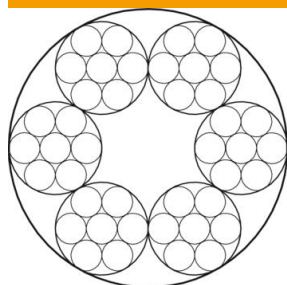

6x7

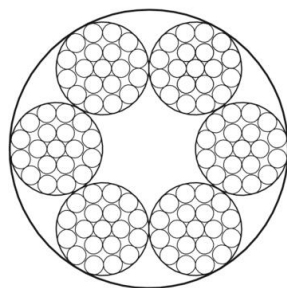

6x19

Technical data

Breaking load	5.29 kN
in rings	50 m
Cable diameter	3 mm