

# Technical data sheet

## Support bracket AS 15

Item number: 6421350



Light-duty support bracket for infinitely adjustable fastening on IS 8 support.  
The support bracket can be fastened to both sides of the I support.

The necessary clamping lug (item no. 6419015), including bolt and nut can be ordered individually for bracket widths 110–160 mm.



St

Steel

FT

Hot-dip galvanised

### Master data

Item number	6421350
Type	AS 15 21 FT
Description 1	Support bracket
Description 2	for IS 8 support
Manufacturer	OBO
Dimension	B210mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	39.4 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,9596 kg CO2e / 1 Piece


# Technical data sheet

## Support bracket AS 15

Item number: 6421350



### Dimensions

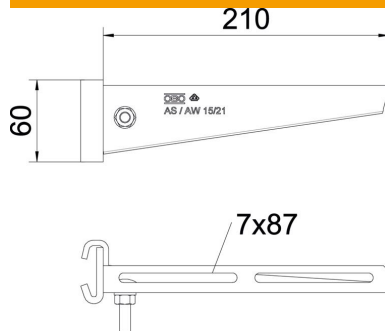


Length	41 mm
Width	210 mm
Height	60 mm
Dimension A	41 mm
Dimension B	210 mm
Dimension H	60 mm

### Technical data

Version for	Support bracket
EPD article	yes
F in kN	1.5 kN
Maintain electrical functions	no
Rustproof steel, pickled	no

### Loads

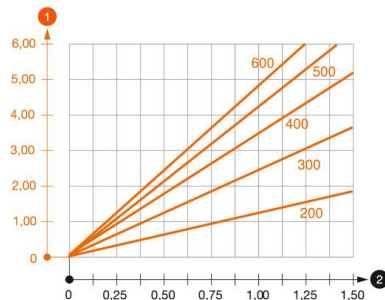

#### Load diagram, bracket type AS 15

- 1 Bending of the bracket tip at permitted bracket load
- 2 Permitted bracket load in kN without man load
- 2 Support width in m
- Load curve with bracket lengths in mm