

Technical data sheet

Support bracket AS 15

Item number: 6421490



Light-duty support bracket for infinitely adjustable fastening on IS 8 support.
The support bracket can be fastened to both sides of the I support.

The necessary clamping lug (item no. 6419015), including bolt and nut can be ordered individually for bracket widths 110–160 mm.



St

Steel

FT

Hot-dip galvanised

Master data

Item number	6421490
Type	AS 15 61 FT
Description 1	Support bracket
Description 2	for IS 8 support
Manufacturer	OBO
Dimension	B610mm
Colour	zinc
Material	Steel
Surface	Hot-dip galvanised
Surface standard	DIN EN ISO 1461
Smallest sales unit	1
Unit of quantity	Piece
Weight	87.1 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	2,3456 kg CO2e / 1 Piece


Technical data sheet

Support bracket AS 15

Item number: 6421490



Dimensions

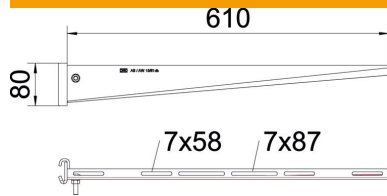


Length	41 mm
Width	610 mm
Height	80 mm
Dimension A	41 mm
Dimension B	610 mm
Dimension H	80 mm

Technical data

Version for	Support bracket
EPD article	yes
F in kN	1.5 kN
Maintain electrical functions	no
Rustproof steel, pickled	no

Loads

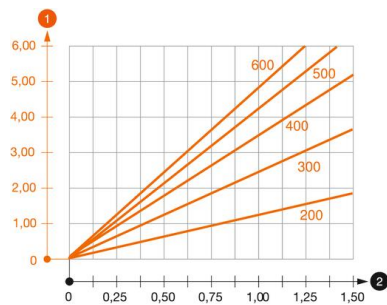

Load diagram, bracket type AS 15

- 1 Bending of the bracket tip at permitted bracket load
- 2 Permitted bracket load in kN without man load
- 2 Support width in m
- Load curve with bracket lengths in mm