

Technical data sheet

T piece for PYROLINE® Con S BSK I90/E30 fire protection duct

 
Item number: 7215632



T piece for PYROLINE® Con S BSK I90/E30 fire protection duct, consisting of fibreglass lightweight concrete which is resistant to water and frost, for the creation of T branches of the duct. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strip.

Including connection screws and sealing strip.



Fibreglass lightweight concrete

Master data		
Item number	7215632	
Description 1	T piece	
Description 2	for BSKH I90/E30	
Manufacturer	OBO	
Dimension	50x60	
Colour	Grey	
Material	Fibreglass lightweight concrete	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	610 kg	
Weight unit	kg/100 pc.	



Technical data sheet

T piece for PYROLINE® Con S BSK I90/E30 fire protection duct

Item number: 7215632



Dimensions

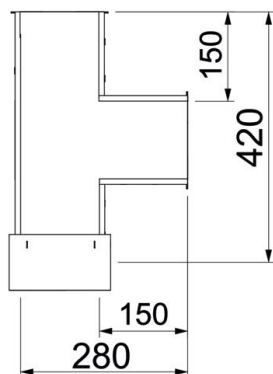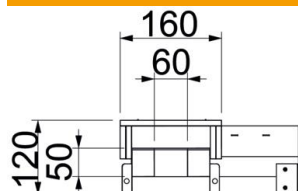

External dimensions	120 x 160
Internal dimensions	50 x 60
Length	280 mm
Dimension B	160 mm
Dimension b	60 mm
Dimension h	50 mm
Dimension H	120 mm
Dimension L	420 mm
Dimension l	280 mm

Technical data

Number of flammable sides	4
Fire resistance class E – function maintenance	30
Fire resistance class I – installation duct	90
With perforation	no
Partitions possible	yes
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete