

# Technical data sheet

## T piece for PYROLINE® Con S BSK I90/E30 fire protection duct

 
Item number: 7215636



T piece for PYROLINE® Con S BSK I90/E30 fire protection duct, consisting of fibreglass lightweight concrete which is resistant to water and frost, for the creation of T branches of the duct. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strip.

Including connection screws and sealing strip.



Fibreglass lightweight concrete

### Master data

Item number	7215636
Description 1	T piece
Description 2	for BSKH I90/E30
Manufacturer	OBO
Dimension	50x110
Colour	Grey
Material	Fibreglass lightweight concrete
Smallest sales unit	1
Unit of quantity	Piece
Weight	780 kg
Weight unit	kg/100 pc.


# Technical data sheet

T piece for PYROLINE® Con S BSK I90/E30 fire protection duct

Item number: 7215636



## Dimensions

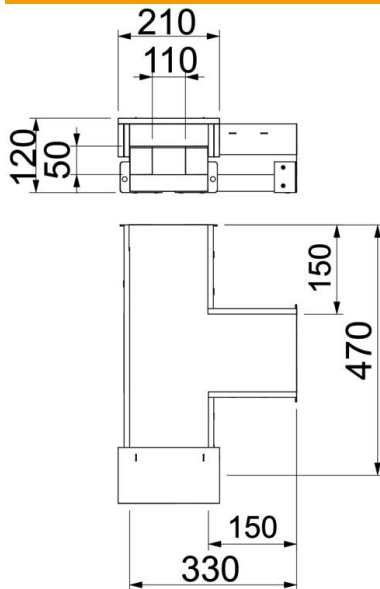

External dimensions	120 x 210
Internal dimensions	50 x 110
Length	330 mm
Dimension B	210 mm
Dimension b	110 mm
Dimension h	50 mm
Dimension H	120 mm
Dimension L	470 mm
Dimension l	330 mm

## Technical data

Number of flammable sides	4
Fire resistance class E – function maintenance	30
Fire resistance class I – installation duct	90
With perforation	no
Partitions possible	yes
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete