

Technical data sheet

T piece for PYROLINE® Con S BSK I90/E30 fire protection duct

 
Item number: 7215648



T piece for PYROLINE® Con S BSK I90/E30 fire protection duct, consisting of fibreglass lightweight concrete which is resistant to water and frost, for the creation of T branches of the duct. Mounted connectors ensure quick mounting in situ, whilst loosely placed covers ensure quick inspection and reassignment.

Including connection screws and sealing strip.

Including connection screws and sealing strip.



Fibreglass lightweight concrete

Master data

Item number	7215648
Description 1	T piece
Description 2	for BSKH I90/E30
Manufacturer	OBO
Dimension	105x260
Colour	Grey
Material	Fibreglass lightweight concrete
Smallest sales unit	1
Unit of quantity	Piece
Weight	1650 kg
Weight unit	kg/100 pc.


Technical data sheet

T piece for PYROLINE® Con S BSK I90/E30 fire protection duct

Item number: 7215648



Dimensions

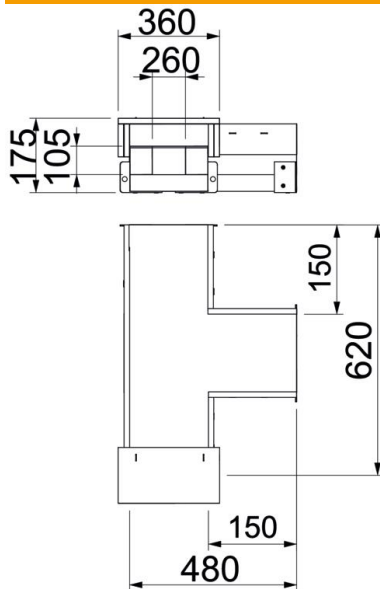

External dimensions	175 x 360
Internal dimensions	105 x 260
Length	480 mm
Dimension B	360 mm
Dimension b	260 mm
Dimension h	105 mm
Dimension H	175 mm
Dimension L	620 mm
Dimension l	480 mm

Technical data

Number of flammable sides	4
Fire resistance class E – function maintenance	30
Fire resistance class I – installation duct	90
With perforation	no
Partitions possible	yes
Jacketing	Without
Material of the insulation	Glass-fibre lightweight concrete