


# Technical data sheet

## BW 10 A2 fastening bracket

Item number: 6019484



Fastening bracket for fastening supports, vertical ladders and constructions on walls, ceilings or steel scaffolding.

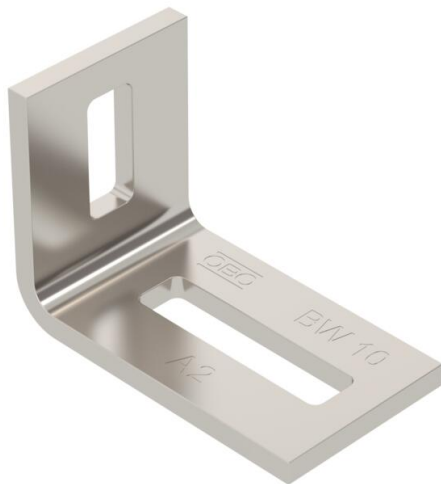

**A2** Stainless steel

**2B** Bright, treated

### Master data

Item number	6019484
Type	BW 10 A2
Description 1	Fastening bracket
Manufacturer	OBO
Dimension	70x50x40
Colour	stainless steel
Material	Stainless steel 1.4301
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	14.2 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,9676 kg CO2e / 1 Piece


# Technical data sheet

## BW 10 A2 fastening bracket


Item number: 6019484



### Dimensions

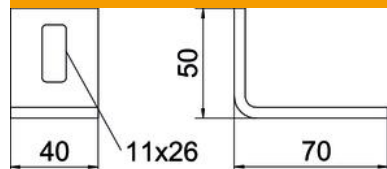

Length	70 mm
Width	40 mm
Height	50 mm

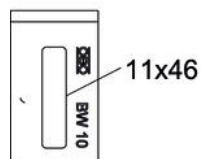

### Technical data

Version for	Fastening bracket
Maintain electrical functions	no
Suitable for profile shapes	U profile
Material thickness	5 mm
With screw accessories	no
Adjustable	no