


Technical data sheet

BW 12 A2 fastening bracket

Item number: 6019504



Fastening bracket for fastening supports, vertical ladders and constructions on walls, ceilings or steel scaffolding.

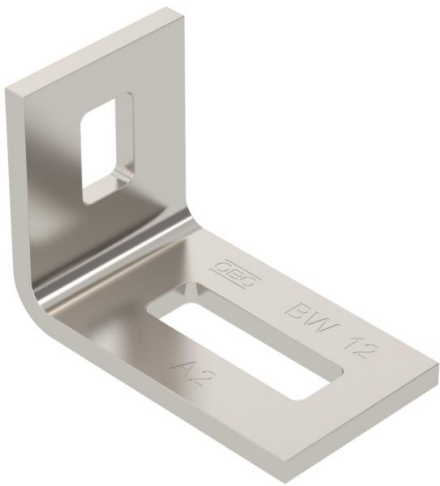

- A2Stainless steel
- 2BBright, treated

Master data	
Item number	6019504
Type	BW 12 A2
Description 1	Fastening bracket
Manufacturer	OBO
Dimension	70x50x40
Colour	stainless steel
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	10
Unit of quantity	Piece
Weight	13.97 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,975 kg CO2e / 1 Piece


Technical data sheet

BW 12 A2 fastening bracket




Item number: 6019504

Dimensions

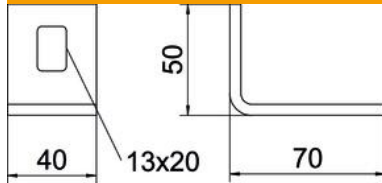

Length	70 mm
Width	40 mm
Height	50 mm

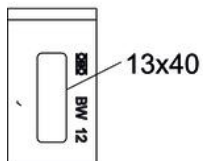

Technical data

Version for	Fastening bracket
Maintain electrical functions	no
Suitable for profile shapes	U profile
Material thickness	5 mm
With screw accessories	no
Adjustable	no