

Technical data sheet

PYROCOMB® Intube half shell

Item number: 7204306



Internally coated half shell, the inner space of which can be fully assigned with cables and electrical installation pipes. For interior application. CE-labelled, European approved construction product according to ETA-13/0904 and German general type approval. Fire resistance up to 120 minutes.

Closing with foam plug included in the delivery. The surface seal is created with PYROCOAT® ASX coating. The system is particularly suitable for underfloor areas.

Details can be found in the mounting instructions/approval.



PVC Polyvinylchloride

Master data

Item number	7204306
Type	CTS-HP200
Description 1	Half-shell
Description 2	internally coated
Manufacturer	OBO
Dimension	200x116x65mm
Colour	Grey
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	20 kg
Weight unit	kg/100 pc.


Technical data sheet

PYROCOMB® Intube half shell




Item number: 7204306

Dimensions

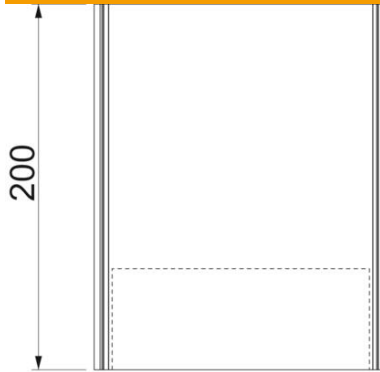

Length	200 mm
Dimension B	118 mm
Dimension d min.	106 mm
Dimension L	200 mm

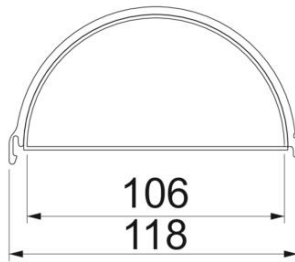

Technical data

Fire protection version	Miscellaneous
Shape	Round
For opening, max.	165 mm
For opening, min.	125 mm
Accessories required	no