


Technical data sheet

Cover for double accessory mounting box for WDK trunking, trunking height 110 mm
Item number: 6194109

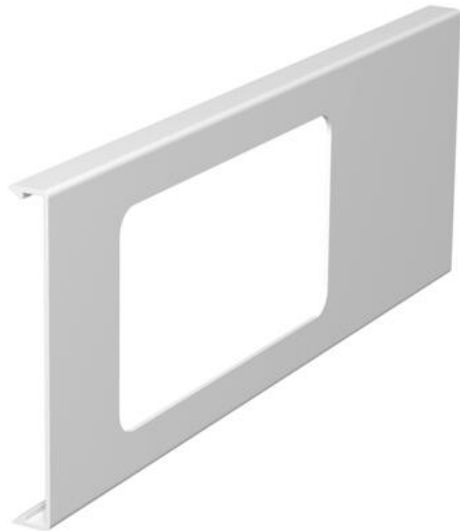

Cover section, double, for device installation in WDK trunking in conjunction with the device installation socket, type 2390.



PVC Polyvinylchloride

Master data

Item number	6194109
Type	D2-2 110RW
Description 1	Cover
Description 2	for double device installation
Manufacturer	OBO
Dimension	110x300mm
Colour	Pure white; RAL 9010
Material	Polyvinylchloride
Smallest sales unit	1
Unit of quantity	Piece
Weight	6.5 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	0,2281 kg CO2e / 1 Piece


Technical data sheet

Cover for double accessory mounting box for WDK trunking, trunking height 110 mm

Item number: 6194109



Dimensions

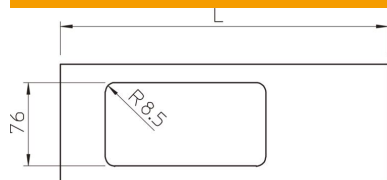

Length	300 mm
Width	108 mm
Height	14 mm

Technical data

Maintain electrical functions	no
Halogen-free	no
Protection rating	IP30
Protection rating IK code	IK04
Permitted temperature range, max.	60 °C
Permitted temperature range, min.	-5 °C