

# Technical data sheet

Deskbox DBV, 2 sockets, VGA, mini jack, 2x RJ45 Cat. 6

Item number: 6116886



Lowerable Deskbox with connection cable for fixed installation on a tabletop, plastic fastening sleeve, painted accordingly in cover shade. It is mounted using a drill hole (Ø102 mm) in the tabletop.

#### Equipment:

- Two black protection contact sockets in 60° connection direction, incl. 3.0 m power cable with angular connector CEE 7/7.
- One VGA 15-pin HDD socket, incl. 3.0 m connection cable with connector.
- One audio jack socket 3.5 mm, incl. 3.0 m connection cable with connector.
- Two data technology couplings RJ45 to RJ45, 1:1 switched, Cat. 6 shielded.

Note: Can be used in tabletops of up to 50 mm thickness.

The ready-for-connection type DBV Deskbox is particularly suitable for the direct supply of workstations with energy, communication and data technology connections.

**Alu** Aluminium

**EL** Anodised

## Master data

Item number	6116886
Type	DBV-MA3A D3S2K
Description 1	Deskbox, lowerable
Description 2	for installation in table tops
Manufacturer	OBO
Colour	aluminium
Material	Aluminium
Surface	Anodised
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	118.23 kg
Weight unit	kg/100 pc.


# Technical data sheet

Deskbox DBV, 2 sockets, VGA, mini jack, 2x RJ45 Cat. 6

Item number: 6116886



## Dimensions

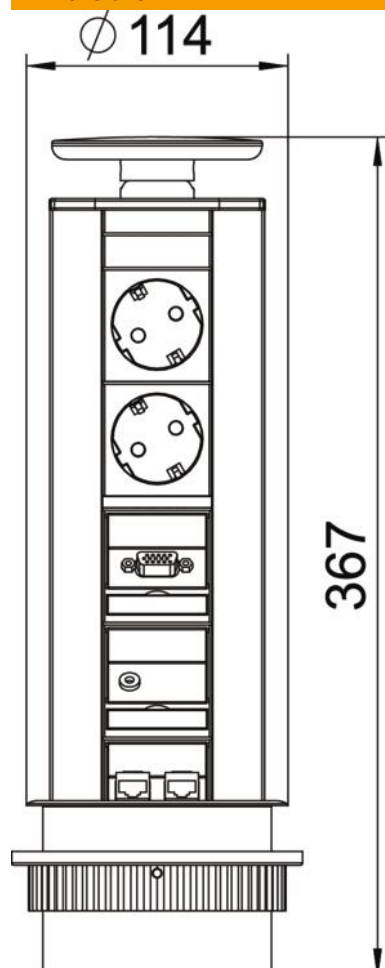

Length

367 mm

# Technical data sheet

Deskbox DBV, 2 sockets, VGA, mini jack, 2x RJ45 Cat. 6

Item number: 6116886



## Technical data

Number of audio connections	1
Number of CAT 5 connections	0
Number of CAT 5E connections	0
Number of CAT 6 connections	2
Number of USB connections	0
Number of VGA connections	1
Number of HDMI connections	0
Number of SCHUKO sockets	2
Version for	Lid, painted silver
Version for	Installation
Extendable	yes
Shape	Round
Foldable	no
Length of the supply cable	3 m
Surge protection	no