

Technical data sheet

Cover for 90° vertical bend, rising, DD

Item number: 7131518



Cover for all rising vertical bends.

The fastening is guaranteed by the overlap of the cable tray covers. The cover can also be fastened using cover clamps.



St

Steel

DD

Strip galvanised zinc/aluminium, Double Dip

Master data

Item number	7131518
Type	DBV 400 S DD
Description 1	Cover for 90° vertical bend
Description 2	rising
Manufacturer	OBO
Dimension	B400mm
Colour	zinc
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	113 kg
Weight unit	kg/100 pc.
CO2 Footprint (GWP) Cradle-to-Gate	4,4464 kg CO2e / 1 Piece


Technical data sheet

Cover for 90° vertical bend, rising, DD

Item number: 7131518



Dimensions

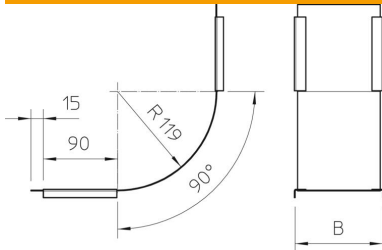

Width	400 mm
Width	16 in
Plate thickness	0.03 in
Plate thickness	0.75 mm
Dimension B	400 mm

Technical data

Bend (angle)	90°
Fastening type	Cover clamp
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Change of direction	Vertical rising
Rustproof steel, pickled	no
Hinged	no