

Technical data sheet

Cover for 90° vertical bend 85, falling, DD

Item number: 7131692



Cover for falling vertical bends of side height 85 mm.
The fastening is guaranteed by the overlap of the cable tray covers. The cover can also be fastened using cover clamps.



- St** Steel
- DD** Strip galvanised zinc/aluminium, Double Dip

Master data		
Item number	7131692	
Description 1	Cover for 90° vertical bend	
Description 2	falling	
Manufacturer	OBO	
Dimension	B600mm	
Colour	zinc	
Material	Steel	
Surface	Strip galvanised zinc/aluminium, Double Dip	
Surface standard	DIN EN 10346	
Smallest sales unit	1	
Unit of quantity	Piece	
Weight	256 kg	
Weight unit	kg/100 pc.	


Technical data sheet

Cover for 90° vertical bend 85, falling, DD

Item number: 7131692



Dimensions

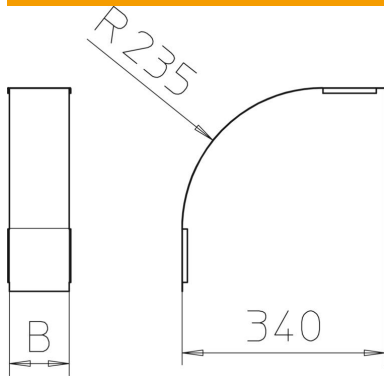

Width	600 mm
Width	24 in
Height	85 mm
Plate thickness	0.03 in
Plate thickness	0.75 mm
Dimension B	600 mm

Technical data

Bend (angle)	90°
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Change of direction	Vertical, falling
Rustproof steel, pickled	no
Hinged	no