

# Technical data sheet

## Cover for variable Magic bend A4

Item number: 6040822



Cover for the variable bend, adjustable to an angle of 0 to 90°, locking through turn buckle and through overlapping with cable tray cover.



**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	6040822
Description 1	Cover for variable bend Magic
Description 2	0 to 90°, for RBMV
Manufacturer	OBO
Dimension	154x272
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	27.5 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Cover for variable Magic bend A4

Item number: 6040822



### Dimensions

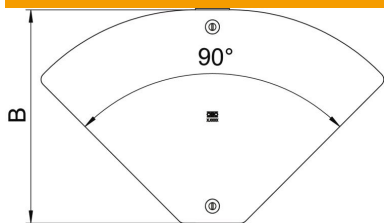

Width	150 mm
Plate thickness	1 mm
Dimension B	150 mm

### Technical data

Bend (angle)	Adjustable
Fastening type	Sash lock
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no
Hinged	no