

Technical data sheet

Cover for variable Magic bend A4

Item number: 6040826



Cover for the variable bend, adjustable to an angle of 0 to 90°, locking through turn buckle and through overlapping with cable tray cover.



A4 Stainless steel

2B Bright, treated

Master data

Item number	6040826
Type	DFBMV 300 A4
Description 1	Cover for variable bend Magic
Description 2	0 to 90°, for RBMV
Manufacturer	OBO
Dimension	304x484
Material	Stainless steel 1.4571
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	78.1 kg
Weight unit	kg/100 pc.


Technical data sheet

Cover for variable Magic bend A4

Item number: 6040826



Dimensions

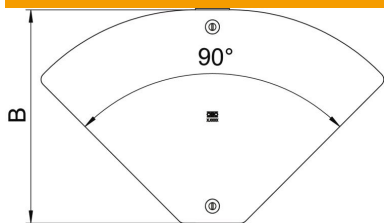

Width	300 mm
Plate thickness	1 mm
Dimension B	300 mm

Technical data

Bend (angle)	Adjustable
Fastening type	Sash lock
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no
Hinged	no