

# Technical data sheet

## Cover for variable Magic bend FS

Item number: 6040766



Cover for the variable bend, adjustable to an angle of 0 to 90°, locking through turn buckle and through overlapping with cable tray cover.



**St** Steel

**FS** Strip galvanized

### Master data

Item number	6040766
Type	DFBMV 300 FS
Description 1	Cover for variable bend Magic
Description 2	0 to 90°, for RBMV
Manufacturer	OBO
Dimension	304x484
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	81.2 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Cover for variable Magic bend FS

Item number: 6040766



### Dimensions

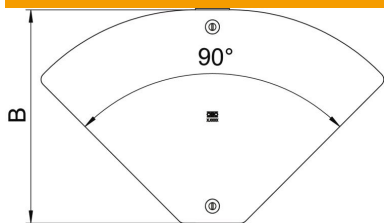

Width	300 mm
Width	12 in
Plate thickness	0.04 in
Plate thickness	1 mm
Dimension B	300 mm

### Technical data

Bend (angle)	Adjustable
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no
Hinged	no