

# Technical data sheet

## Cover for variable Magic bend DD

Item number: 6040792



Cover for the variable bend, adjustable to an angle of 0 to 90°, locking through turn buckle and through overlapping with cable tray cover.



**St** Steel

**DD** Strip galvanised zinc/aluminium, Double Dip

### Master data

Item number	6040792
Type	DFBMV 600 DD
Description 1	Cover for variable bend Magic
Description 2	0 to 90°, for RBMV
Manufacturer	OBO
Dimension	604x908
Material	Steel
Surface	Strip galvanised zinc/aluminium, Double Dip
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	340.6 kg
Weight unit	kg/100 pc.


# Technical data sheet

## Cover for variable Magic bend DD

Item number: 6040792



### Dimensions

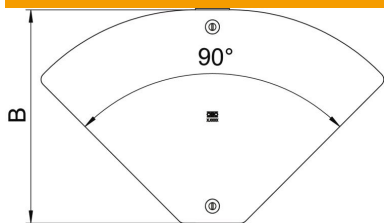

Width	600 mm
Plate thickness	1.25 mm
Dimension B	600 mm

### Technical data

Bend (angle)	Adjustable
Fastening type	Sash lock
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no
Hinged	no