

Technical data sheet

Cover for variable Magic bend FS

Item number: 6040772



Cover for the variable bend, adjustable to an angle of 0 to 90°, locking through turn buckle and through overlapping with cable tray cover.



St Steel

FS Strip galvanized

Master data

Item number	6040772
Type	DFBMV 600 FS
Description 1	Cover for variable bend Magic
Description 2	0 to 90°, for RBMV
Manufacturer	OBO
Dimension	604x908
Material	Steel
Surface	Strip galvanized
Surface standard	DIN EN 10346
Smallest sales unit	1
Unit of quantity	Piece
Weight	340.6 kg
Weight unit	kg/100 pc.


Technical data sheet

Cover for variable Magic bend FS

Item number: 6040772



Dimensions

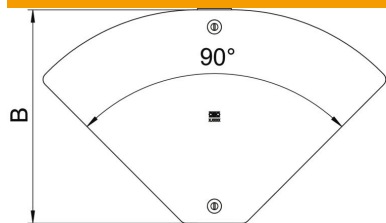

Width	600 mm
Width	24 in
Plate thickness	0.05 in
Plate thickness	1.25 mm
Dimension B	600 mm

Technical data

Bend (angle)	Adjustable
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	no
Suitable for cable tray	yes
Rustproof steel, pickled	no
Hinged	no