

# Technical data sheet

## Cover for 45° bend A4

Item number: 7133984



Cover for 45° bend with pre-mounted turn buckles.  
The cover can be used with fittings of all side heights.




**A4** Stainless steel

**2B** Bright, treated

### Master data

Item number	7133984
Description 1	45° bend cover
Description 2	with sash locks, for RB 45 100
Manufacturer	OBO
Dimension	B100mm
Material	Stainless steel
Surface	Bright, treated
Surface standard	
Smallest sales unit	1
Unit of quantity	Piece
Weight	14 kg
Weight unit	kg/100 pc.

### Dimensions

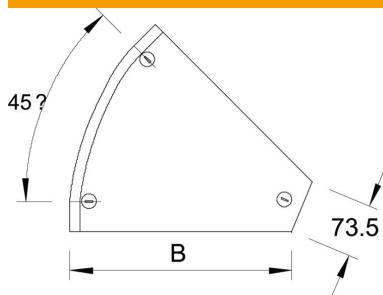

Width	100 mm
Width	4 in
Height	35 mm
Plate thickness	0.04 in
Plate thickness	1 mm
Dimension B	100 mm

# Technical data sheet

Cover for 45° bend A4

Item number: 7133984



## Technical data

Bend (angle)	45°
Fastening type	Sash lock
Maintain electrical functions	no
Suitable for mesh cable tray	no
Suitable for cable ladder	yes
Suitable for cable tray	yes
Change of direction	Horizontal
Rustproof steel, pickled	no
Hinged	no